


# E12205



## Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

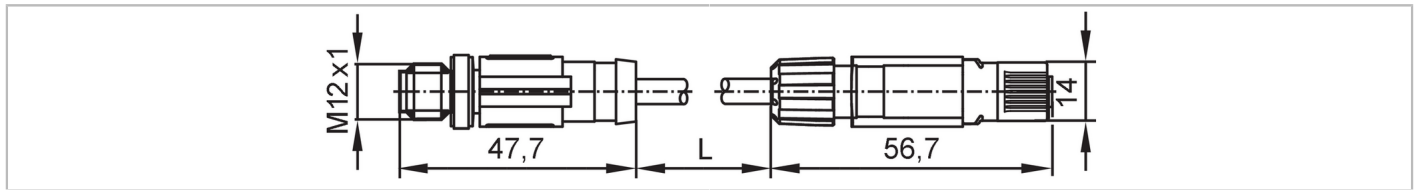

Application	
Special feature	gold-plated contacts; screened cable
Design	Ethernet cable, D-coded
Application	Industrial applications; Cross-over patch cable
Electrical data	
Operating voltage [V]	48 AC / 60 DC
Protection class	III
Max. current load total [A]	1
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 65; IP 67; (M12 plug / RJ45 plug: IP 20)
Mechanical data	
Weight [g]	1357
Molded-body material	TPU (urethane) / PA
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug M12	
Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU (urethane), black; Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm	

# E12205




## Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

### Electrical connection

Cable: 20 m, PVC, green, Ø 6.5 mm, screened; PROFINET; 4 x 0.34 mm<sup>2</sup> (7 x Ø 0.25 mm )

### Connection

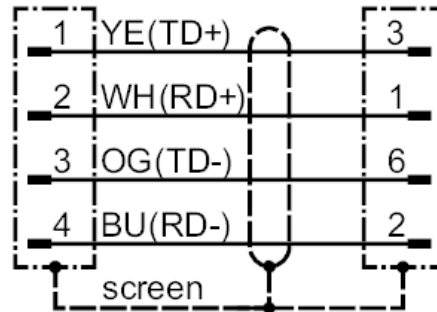

### Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Contacts: 8, gold-plated; Moulded body: PA

