


E12205



Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

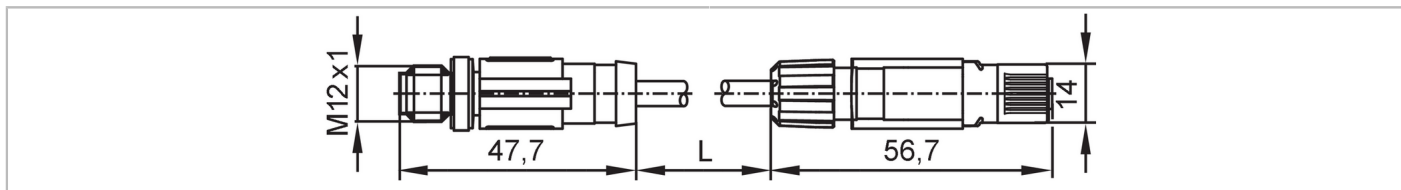

Application	
Special feature	gold-plated contacts; screened cable
Design	Ethernet cable, D-coded
Application	Cross-over patch cable

Electrical data	
Operating voltage [V]	48 AC / 60 DC
Protection class	III
Max. current load total [A]	1

Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 65; IP 67; (M12 plug / RJ45 plug: IP 20)

Mechanical data	
Weight [g]	1357
Molded-body material	TPU (urethane) / PA
Material nut	diecast zinc, nickel-plated

Remarks	
Pack quantity	1 pcs.

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: TPU (urethane), black; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.4 Nm



E12205




Ethernet connection cable

VSTGN040ZDS0020L04STGP040--S

Electrical connection

Cable: 20 m, PVC, green, Ø 6.5 mm, screened; PROFINET; 4 x 0.34 mm² (7 x Ø 0.25 mm)

Connection

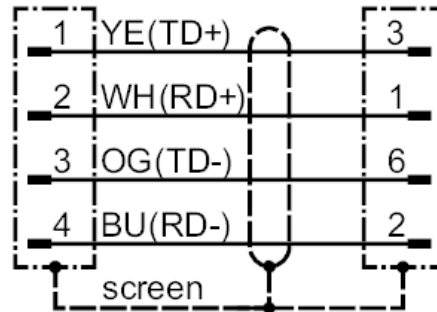

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PA; Contacts: gold-plated

