


E12229



Female cordset

ADOAH040VAS0020G04

Article no longer available - archive entry

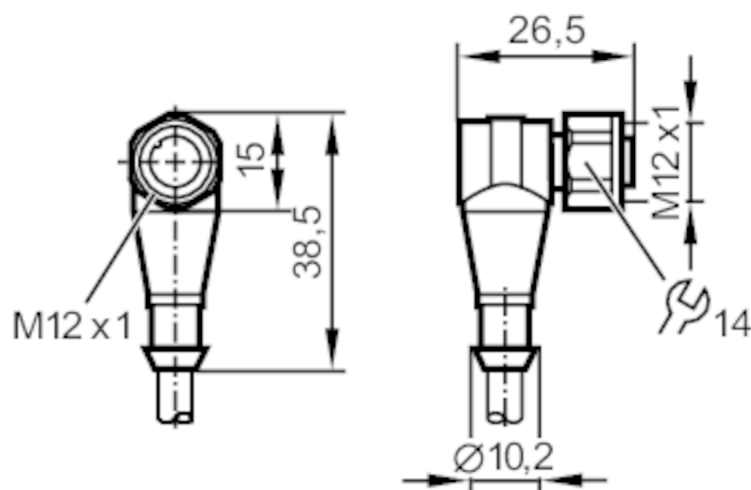

Application

System	Free from silicone; gold-plated contacts; screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 67

Mechanical data

Weight	[g]	1046.6
Dimensions	[mm]	26.5 x 15 x 38.5
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E12229



Female cordset

 
ADOAH040VAS0020G04

Electrical connection


Cable: 20 m, PVC, orange, Ø 5.3 mm, screened; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: shield not connected



Connection

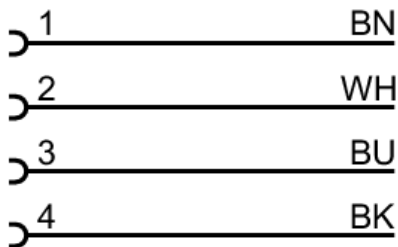

Core colors :
BK = black
BN = brown
BU = blue
WH = white