


E12237



Female cordset

ADOAH080MSS0015B08

For 8-wire cordsets the core colors are not standardized.
Please note the wiring of the sensor and the cordsets (see data sheet).

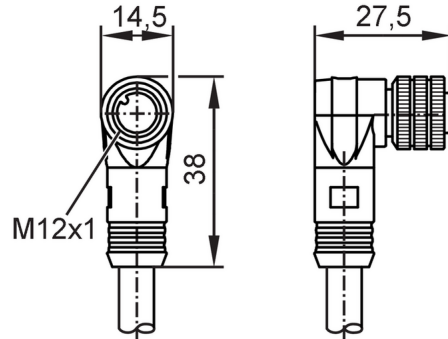

Application

Application Industrial applications

Electrical data

Operating voltage [V] < 30 AC / < 36 DC
Max. current load total [A] 2

Operating conditions

Ambient temperature [°C] -40...80
Protection IP 68

Mechanical data

Weight [g] 813.5
Dimensions [mm] 27.5 x 14.5 x 38
Molded-body material TPU (urethane)
Material nut brass, nickel-plated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 15 m, PUR, black, Ø 6.6 mm; 8 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Contacts: 8; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 1...1.5 Nm




E12237



Female cordset

ADOAH080MSS0015B08

Connection

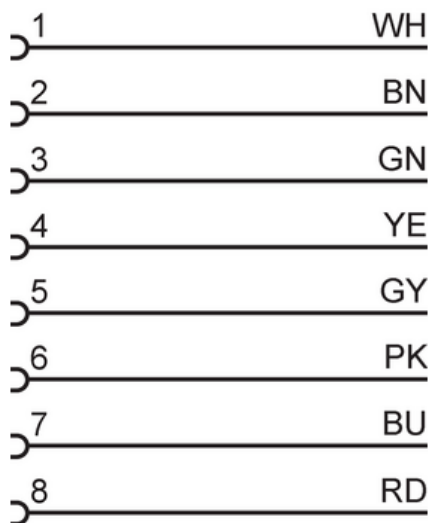

Colors to DIN 47100

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow