


# E12281



## Connection cable

VDOGH080MSS0002H08STGH080MSS

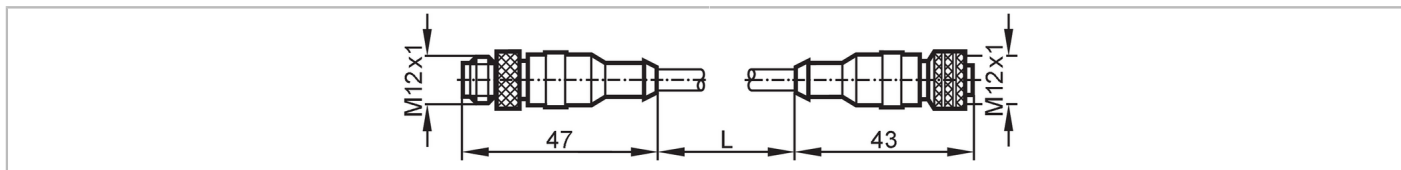

### Application

Special feature	Halogen-free
Application	Industrial applications

### Electrical data

Operating voltage [V]	< 30 AC / < 36 DC
-----------------------	-------------------

### Operating conditions

Ambient temperature [°C]	-25...80
Protection	IP 68

### Mechanical data

 
Weight [g]	152.3
Molded-body material	PUR
Material nut	brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 6.8 mm; 8 x 0.25 mm<sup>2</sup>

### Connection

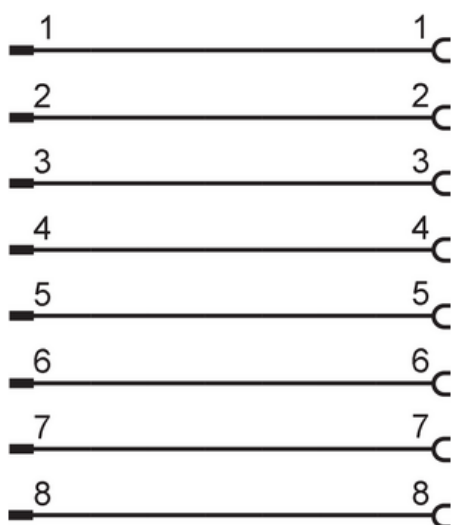

# E12281



## Connection cable

VDOGH080MSS0002H08STGH080MSS

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

