


# E12281



## Connection cable

 
VDOGH080MSS0002H08STGH080MSS

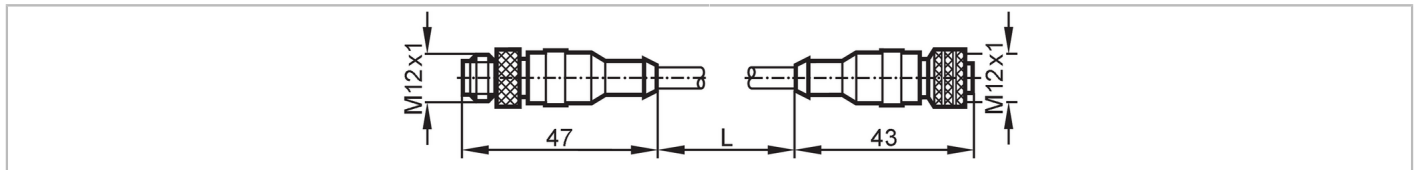

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	152.3
Molded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 6.8 mm; 8 x 0.25 mm²

#### Connection

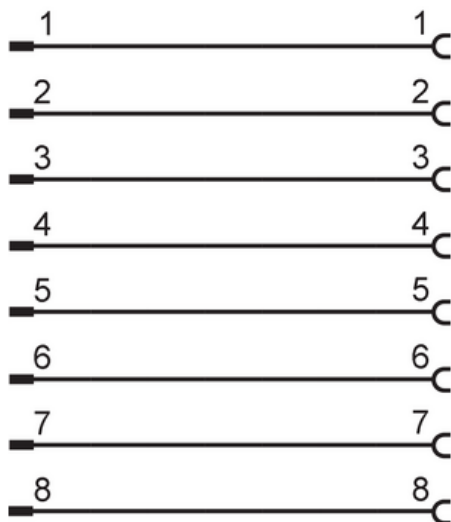

# E12281



## Connection cable

VDOGH080MSS0002H08STGH080MSS

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

