


E12289



Wirable plug

SSTGN040ZDSFKSG

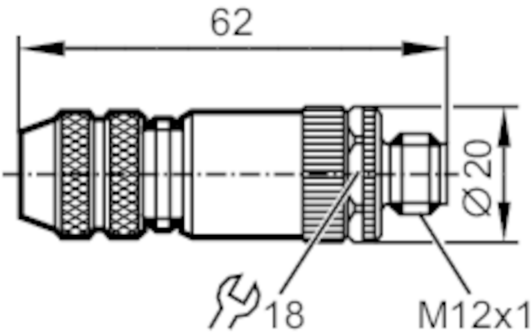

Application		
System		Free from silicone; gold-plated contacts
Design		Ethernet cable, D-coded
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	44.6
Dimensions	[mm]	20.2 x 20.2 x 63
Material		diecast zinc nickel-plated
Molded-body material		diecast zinc, nickel-plated
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E12289



Wirable plug

SSTGN040ZDSFKSG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm; AWG 18

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: diecast zinc, nickel-plated; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: shieldable



Connection

