


Wiring block

ZD08F04HMSS0002H10

Article to be discontinued

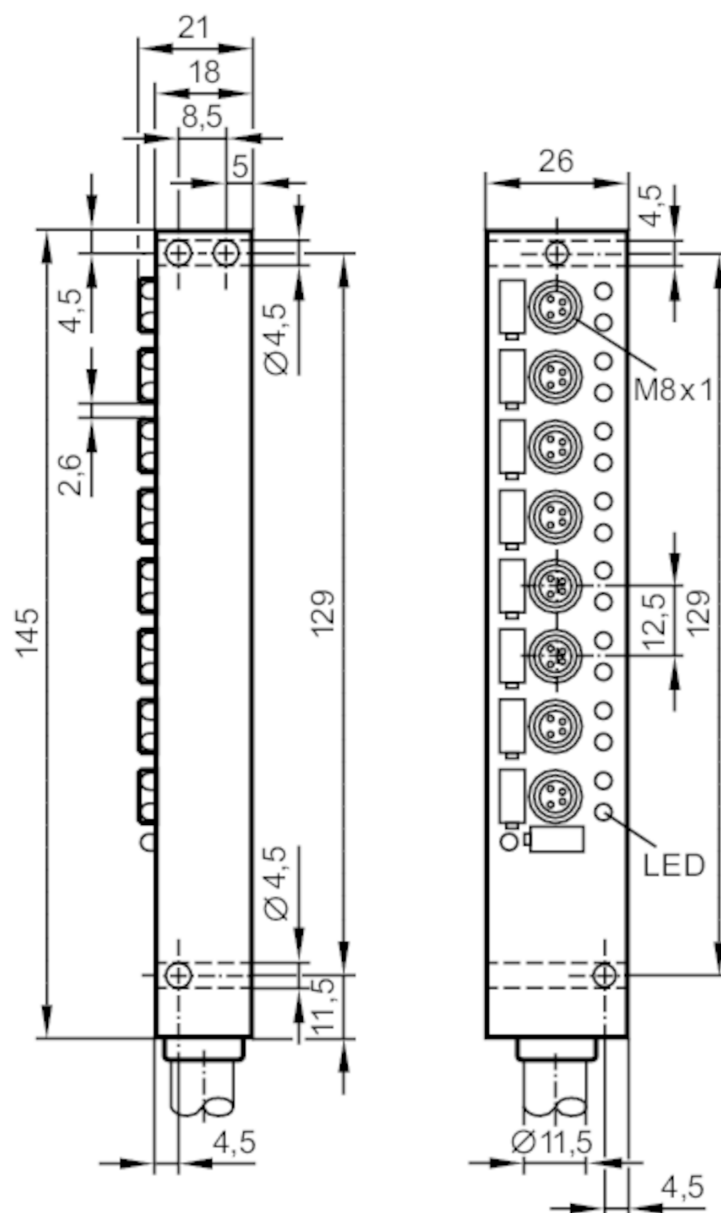

Application

System	Halogen-free; gold-plated contacts; Drag chain suitability
--------	--

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	6

Operating conditions

Ambient temperature	[°C]	-20...80
Protection		IP 67


E12293



Wiring block

ZDO8F04HMSS0002H10

Mechanical data		
Weight	[g]	384.2
Dimensions	[mm]	21 x 26 x 145
Material		PBT-GF20; brass nickel-plated
Molded-body material		PBT-GF 20 / brass, nickel-plated
Number of ports splitter box		8
Connector type		M8
Drag chain suitability		yes
Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	Bending cycles	> 5 Mio.
	Torsional strain	± 180 °/m
Displays / operating elements		
Display	Switching status	16 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, PUR, Halogen-free, black, Ø 11.4 mm; 16 x 0.34 mm² (42 x Ø 0.1 mm) + 2 x 0.75 mm² (96 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 8 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated		

 

E12293



Wiring block

ZDO8F04HMSS0002H10

Connection



Core colors :

BK = black
 BN = brown
 BU = blue
 GN = green
 GY = grey
 PK = pink
 RD = red
 VT = lilac
 WH = white
 YE = yellow

E12293

Wiring block

ZDO8F04HMSS0002H10

