


E12330



Y/T splitter

Y-Splitter M12/2xM12 DO/ST

Article no longer available - archive entry

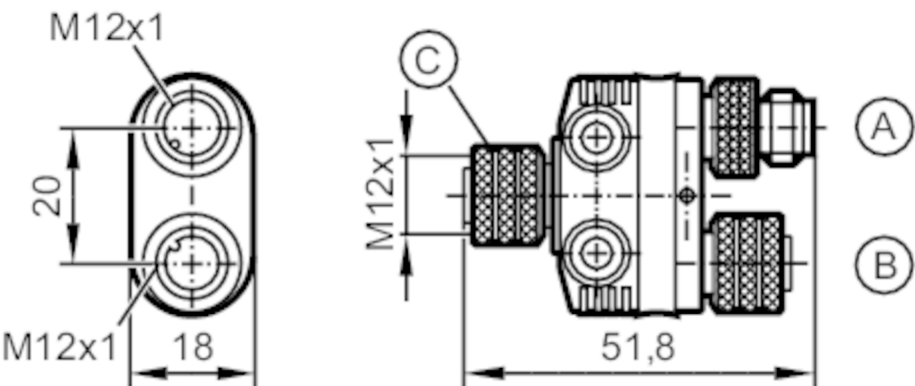

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	29.6
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E12330




Y/T splitter

Y-Splitter M12/2xM12 DO/ST

Electrical connection

Connection

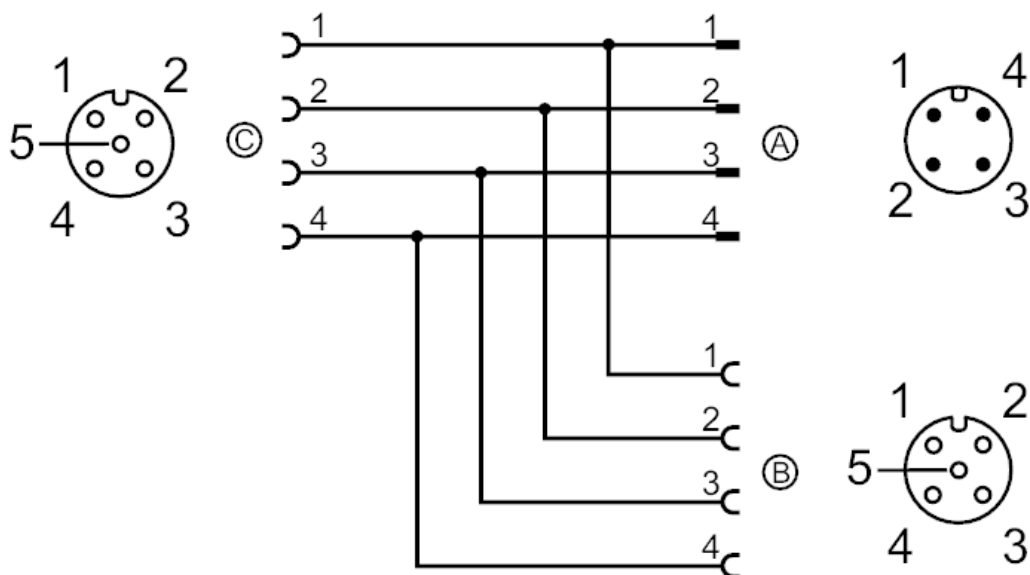

Electrical connection - Socket

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

Electrical connection - plug

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated