


E12352



Female cordset

ADOAH050MSS0010K05

Article no longer available - archive entry

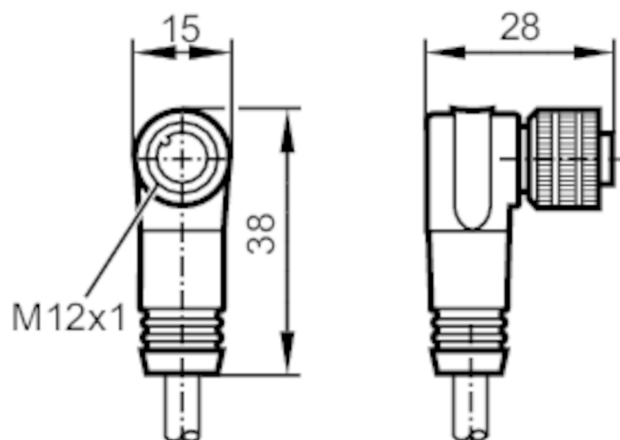

Application

System	Free from silicone; gold-plated contacts; screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	444.6
Dimensions	[mm]	28 x 15 x 38
Material		PUR
Molded-body material		PUR
Material nut		stainless steel

Remarks

Pack quantity	1 pcs.
---------------	--------

E12352



Female cordset


ADOAH050MSS0010K05

Electrical connection


Cable: 10 m, PUR, black, Ø 5.3 mm, screened; 5 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 1.0...1.5 Nm; Shielded connection cable: shield connected

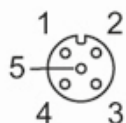

Connection

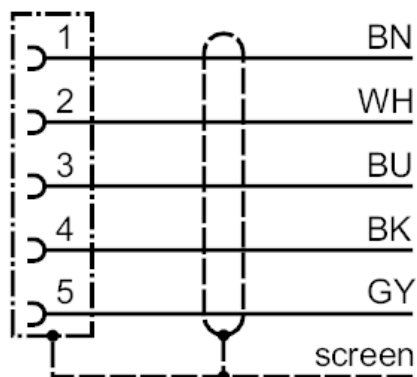

Core colors :	
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white