


# E12354



## Female wirable connectors

SDOGH040MSSFKSG

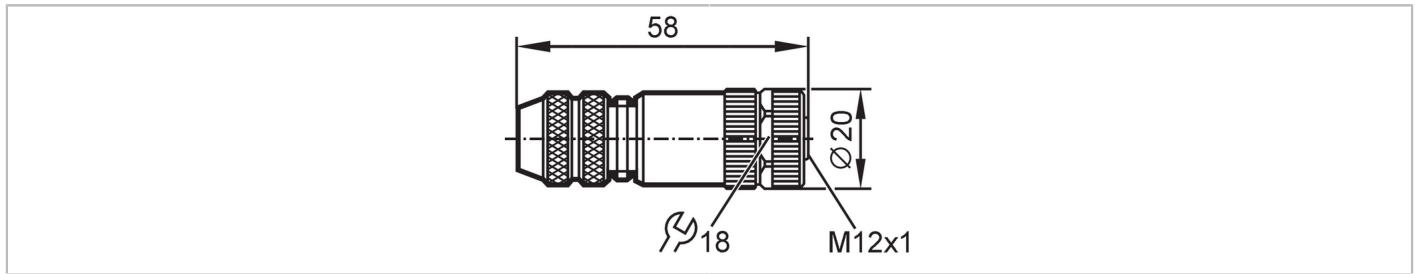

Application	
Special feature	Free from silicone; gold-plated contacts
Design	Ethernet cable, D-coded
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 45 AC / < 70 DC
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 67
Mechanical data	
Weight [g]	46.7
Dimensions [mm]	20 x 20 x 58
Molded-body material	diecast zinc, nickel-plated
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
screw terminals: ...0.75 mm <sup>2</sup> ; Cable sheath: Ø 6...8 mm	
Electrical connection - Socket	
Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: diecast zinc, nickel-plated; Locking: diecast zinc, nickel-plated; Shielded connection cable: shieldable	

# E12354



## Female wirable connectors

SDOGH040MSSFKSG

### Connection

