


# E12355



## Wirable plug

SSTGH040MSSFKSG

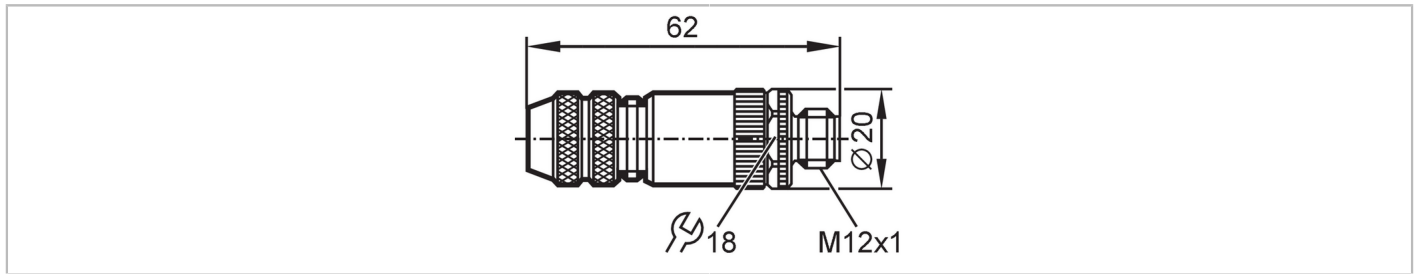

Application	
Special feature	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 45 AC / < 70 DC
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 67
Mechanical data	
Weight [g]	44.4
Dimensions [mm]	20.2 x 20.2 x 63
Molded-body material	diecast zinc, nickel-plated
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
screw terminals: ...0.75 mm <sup>2</sup> ; Cable sheath: Ø 6...8 mm	
Electrical connection - plug	
Connector: 1 x M12, straight; coding: B; Contacts: 4, gold-plated; Moulded body: diecast zinc, nickel-plated; Locking: diecast zinc, nickel-plated; Shielded connection cable: shieldable	

# E12355

## Wirable plug

SSTGH040MSSFKSG



### Connection

