


E12360



Connection cable

VDOGH080MSS0010H08STGH080MSS

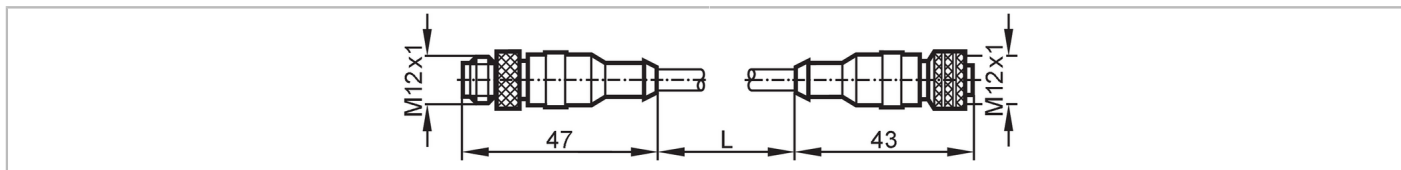

Application

Special feature	Halogen-free
Application	Industrial applications

Electrical data

Operating voltage [V]	< 30 AC / < 36 DC
-----------------------	-------------------

Operating conditions

Ambient temperature [°C]	-25...80
Protection	IP 68

Mechanical data


Weight [g]	617.5
Molded-body material	PUR
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 6.8 mm; 8 x 0.25 mm²

Connection

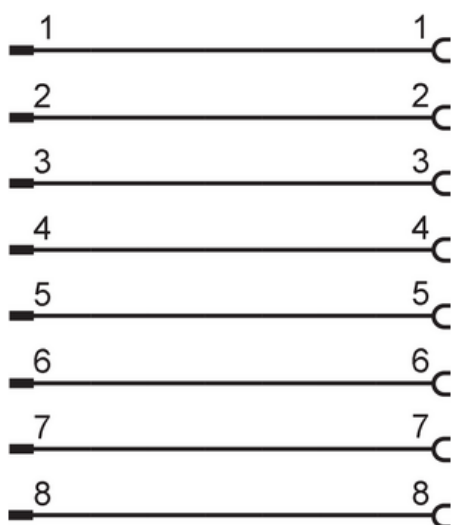

E12360



Connection cable

VDOGH080MSS0010H08STGH080MSS

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

