


# E12385



## Bulk cable

CABLE/100M/ PUR/4X0,34/GR

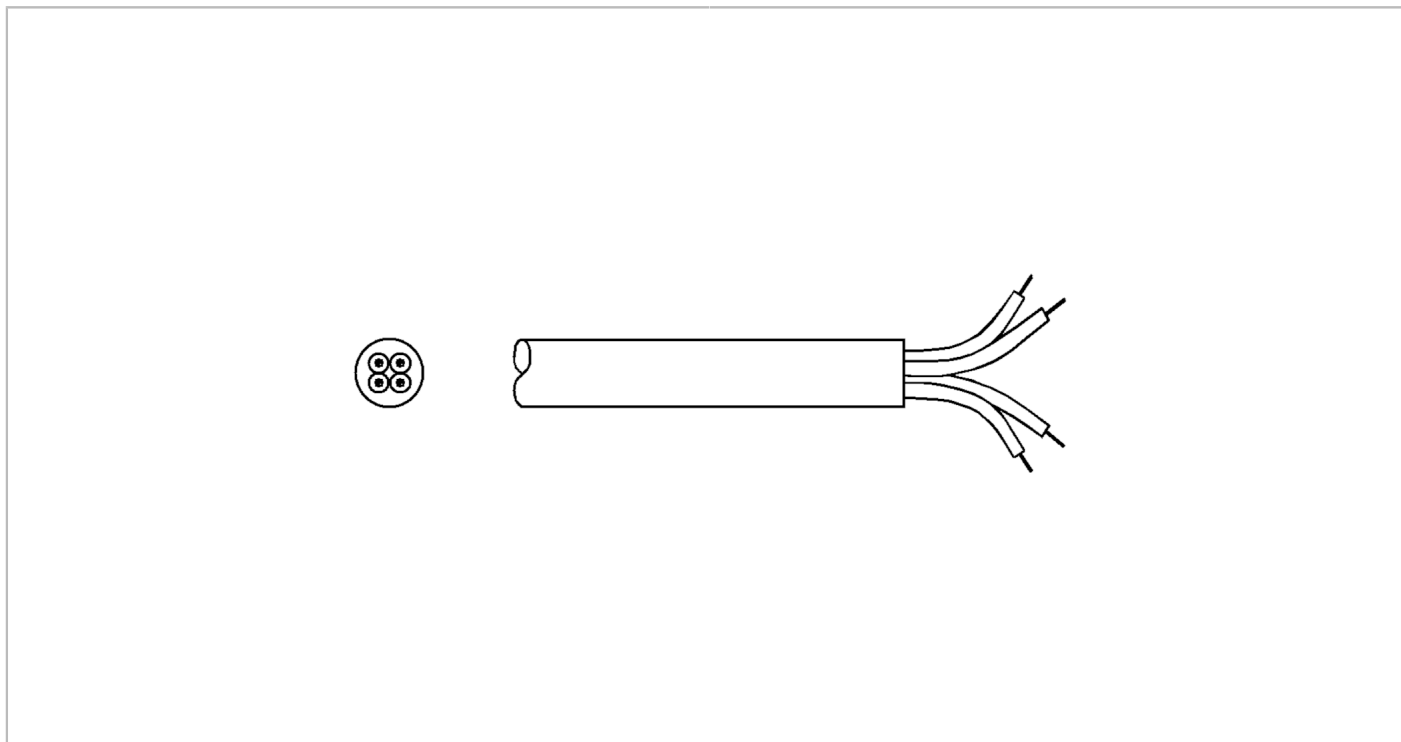

### Application

Special feature	Halogen-free; Drag chain suitability
-----------------	--------------------------------------

### Operating conditions

Ambient temperature	[°C]	-40...90
Ambient temperature (moving)	[°C]	-25...90

### Mechanical data

Weight	[g]	3025
Drag chain suitability		yes
Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup>
	Bending cycles	> 2 Mio.
	Torsional strain	± 180 °/m

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 100 m, PUR, Halogen-free, grey, Ø 4.9 mm; not irradiated (can be recycled); resistant to welding sparks; 4 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )