


# E12387



## Female cordset

ADOGH080VAS0025E08

For 8-wire cordsets the core colors are not standardized.  
Please note the wiring of the sensor and the cordsets (see data sheet).

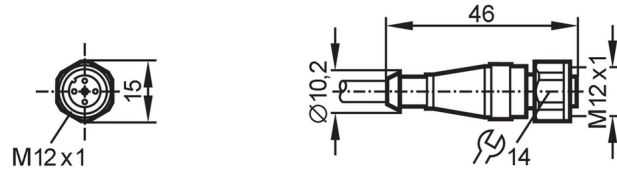

Application	
Special feature	Free from silicone; gold-plated contacts
Application	sanitary and wet areas in the food industry
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Max. current load total [A]	2
Operating conditions	
Ambient temperature [°C]	-25...100
Protection	IP 68; IP 69K
Mechanical data	
Weight [g]	1612.5
Dimensions [mm]	15 x 15 x 46
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Sealing material	EPDM
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 25 m, PVC, orange, Ø 5.9 mm; 8 x 0.25 mm <sup>2</sup> (32 x Ø 0.1 mm )	
Electrical connection - Socket	
Connector: 1 x M12, straight; coding: A; Contacts: 8, gold-plated; Moulded body: PVC, orange; Locking: stainless steel (1.4404 / 316L); sealing: EPDM; Tightening torque: 0.7...0.9 Nm	


# E12387



## Female cordset

ADOGH080VAS0025E08

### Connection

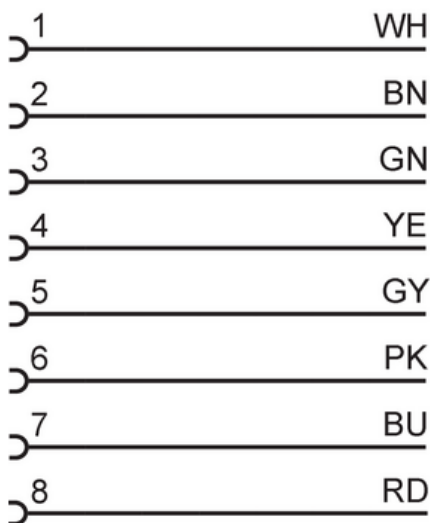

Colors to DIN 47100  
Core colors :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow