


# E12387



## Female cordset

ADOGH080VAS0025E08

For 8-wire cordsets the core colors are not standardized.  
Please note the wiring of the sensor and the cordsets (see data sheet).

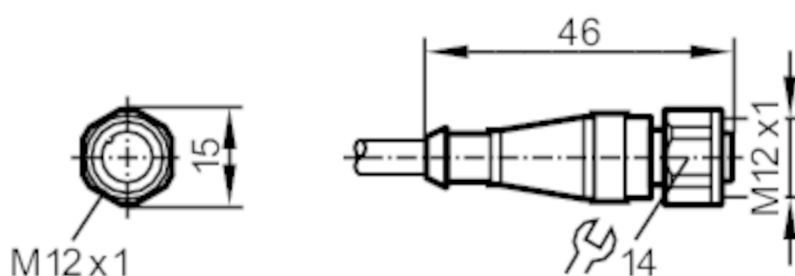

### Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	2

### Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

### Mechanical data

Weight	[g]	1612.5
Dimensions	[mm]	15 x 15 x 46
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

### Remarks

Pack quantity	1 pcs.
---------------	--------

# E12387



## Female cordset


ADOGH080VAS0025E08

### Electrical connection

Cable: 25 m, PVC, orange, Ø 5.9 mm; 8 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

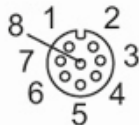

### Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

	Colors to DIN 47100
	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow