


# E18402



## Female cordset

ADOGH040MSC0002X04

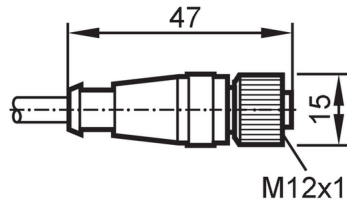

### Application

Special feature	gold-plated contacts
Application	Industrial applications

### Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

### Operating conditions

Ambient temperature	[°C]	-45...105
Protection		IP 68

### Mechanical data

Weight	[g]	158.757
Dimensions	[mm]	15 x 15 x 47
Molded-body material		TPE
Material nut		zinc, PTFE coated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 2 m, yellow; 4 x 0.75 mm<sup>2</sup> / AWG 18

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: TPE; Locking: zinc, PTFE coated




# E18402



## Female cordset

ADOGH040MSC0002X04

### Connection

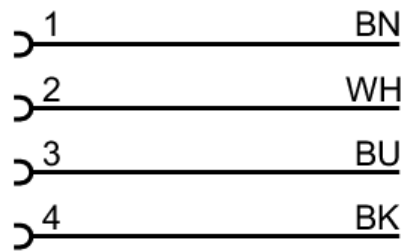

Core colors :

BK =	black
BN =	brown
BU =	blue
WH =	white