


E18404



Female cordset

ADOGH040MSC0010X04

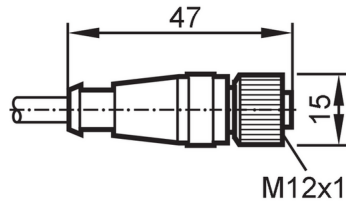

Application

Special feature	gold-plated contacts
Application	Industrial applications

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-45...105
Protection		IP 68

Mechanical data

Weight	[g]	771.106
Dimensions	[mm]	15 x 15 x 47
Molded-body material		TPE
Material nut		zinc, PTFE coated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 10 m, yellow; 4 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: TPE; Locking: zinc, PTFE coated




E18404



Female cordset

ADOGH040MSC0010X04

Connection

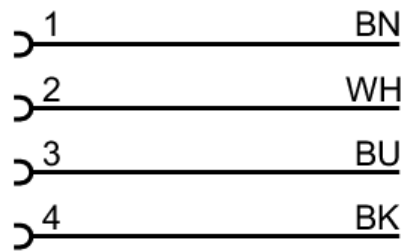

Core colors :
BK = black
BN = brown
BU = blue
WH = white