


E18413



Connection cable

VDOAH040MSC00.3X04STGH040MSC

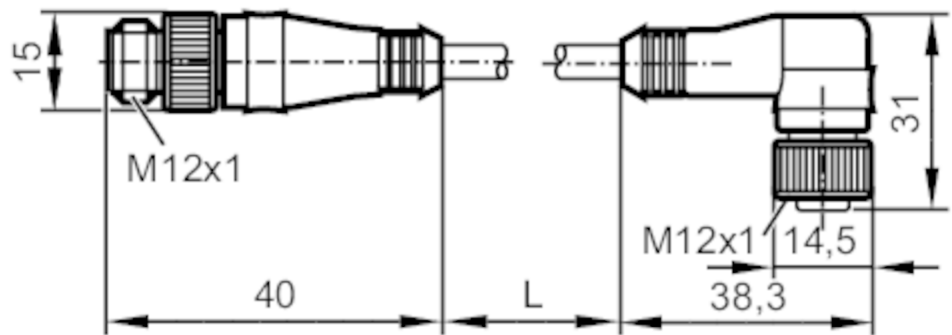

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	45.359
Dimensions	[mm]	15 x 15 x 40
Material		TPE yellow
Molded-body material		TPE
Material nut		zinc, PTFE coated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated



E18413




Connection cable

VDOAH040MSC00.3X04STGH040MSC

Electrical connection

Cable: 0.3 m, yellow; 4 x 0.75 mm² / AWG 18

Connection

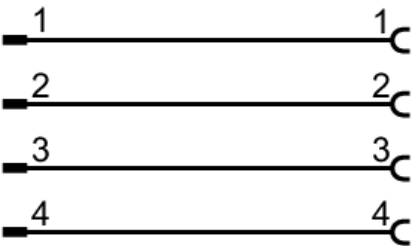

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated

