


E18422



Connection cable


RJ45 to M12 Jumper 5m PUR

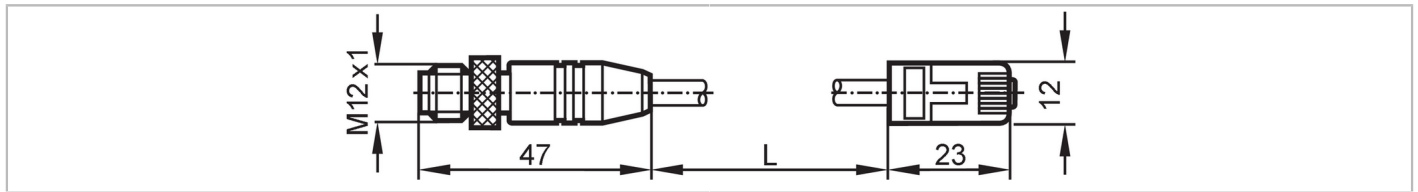

Application	
Design	Ethernet cable, D-coded
Application	Patch cable; Industrial applications
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	323
Molded-body material	PUR / PC
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug M12

 
Connector: 1 x M12, straight; coding: D; Contacts: 4; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 5 m, PUR, green, Ø 6.2 mm; 2 x 2 x 0.38 mm²

Connection

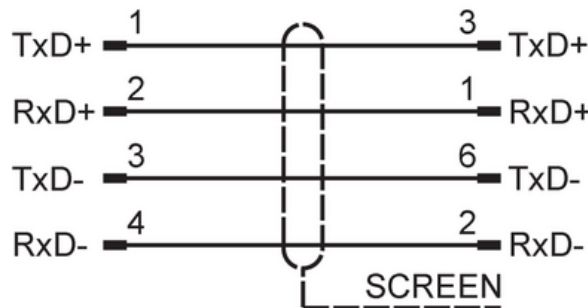

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Contacts: 8; Moulded body: PC

