


E18422



Connection cable

RJ45 to M12 Jumper 5m PUR

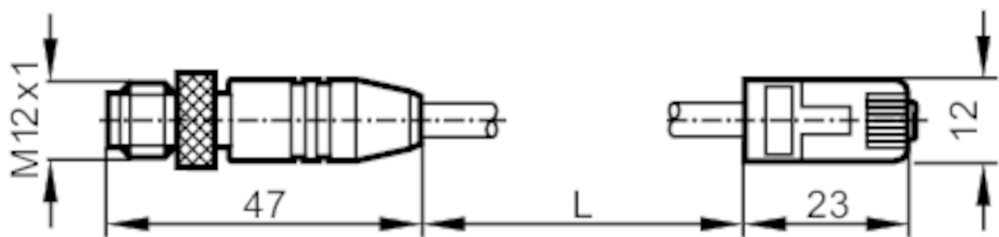

Application		
Design		Ethernet cable, D-coded
Application		Patch cable
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data		
Weight	[g]	323
Material		PUR / PC
Molded-body material		PUR / PC
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug M12		

Connector: 1 x M12, straight; coding: D; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E18422




Connection cable

RJ45 to M12 Jumper 5m PUR

Electrical connection

Cable: 5 m, PUR, green, Ø 6.2 mm; 2 x 0.38 mm²

Connection

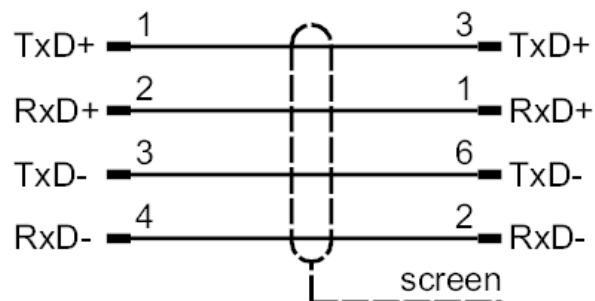

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

