


# E18423



## Connection cable

VDOGH040MSS0010X04GXS

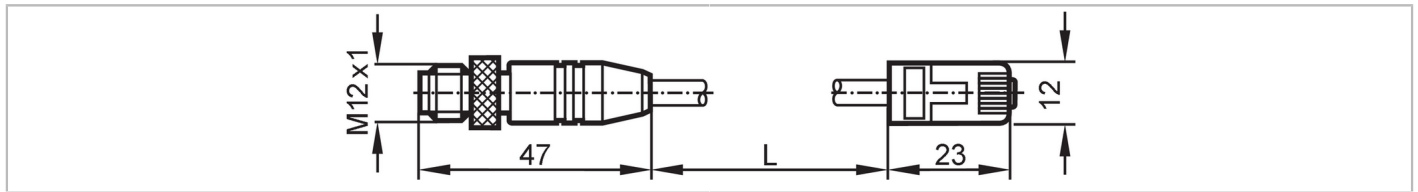

### Application

Special feature	screened cable
Design	Ethernet cable, D-coded
Application	Cross-over patch cable; Patch cable; Industrial applications

### Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 42; (M12 plug / RJ45 plug)

### Mechanical data

Weight	[g]	703.068
Molded-body material		PUR / PC
Material nut		brass, nickel-plated

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection - plug M12


Connector: 1 x M12, straight; coding: D; Contacts: 4; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 10 m, PUR, green, Ø 6.2 mm, screened; 2 x 0.38 mm<sup>2</sup>

### Connection

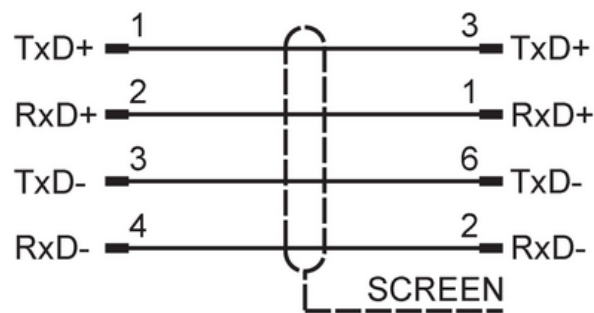

### Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Contacts: 8; Moulded body: PC

