


# E18516



## Female cordset

ADOGH040ZDS0020H04

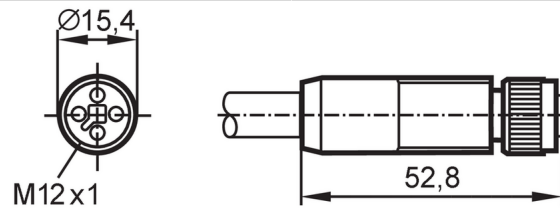

### Application

Special feature	gold-plated contacts
Design	Power cable, T-coded
Application	Industrial applications

### Electrical data

Operating voltage	[V]	< 60 AC
Max. current load total	[A]	12

### Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

### Mechanical data

Weight	[g]	2081.08
Dimensions	[mm]	15.4 x 15.4 x 52.8
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 20 m, PUR, black, Ø 8 mm; 4 x 1.5 mm<sup>2</sup>

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: T; Contacts: 4, gold-plated; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated




# E18516



## Female cordset

ADOGH040ZDS0020H04

### Connection

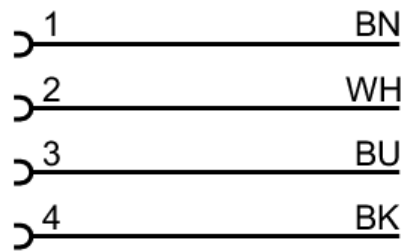

Core colors :

BK =	black
BN =	brown
BU =	blue
WH =	white