


E18516



Female cordset


ADOGH040ZDS0020H04

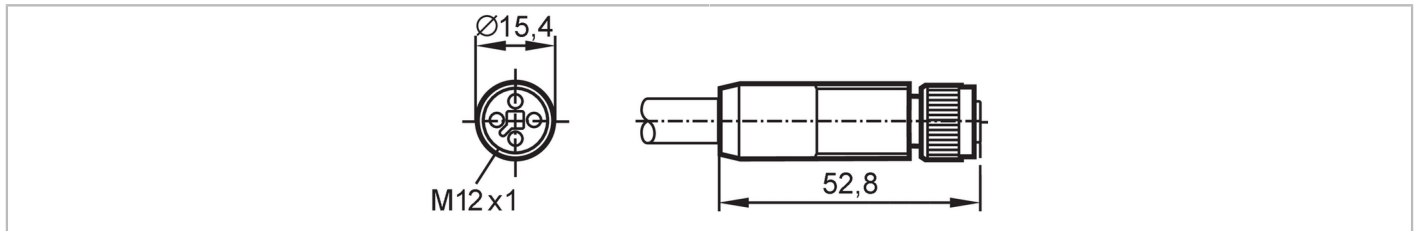


Application		
Special feature		gold-plated contacts
Design		Power cable, T-coded
Application		Industrial applications
Electrical data		
Operating voltage	[V]	< 60 AC
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	2081.08
Dimensions	[mm]	15.4 x 15.4 x 52.8
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection
 Cable: 20 m, PUR, black, Ø 8 mm; 4 x 1.5 mm²

 Electrical connection - Socket
 Connector: 1 x M12, straight; coding: T; Contacts: 4, gold-plated; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated



Connection

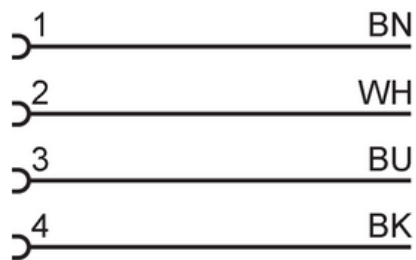

Core colors :
 BK = black
 BN = brown
 BU = blue
 WH = white