


E18520



Female wirable connectors

SDOGH040MSSFKPG-T

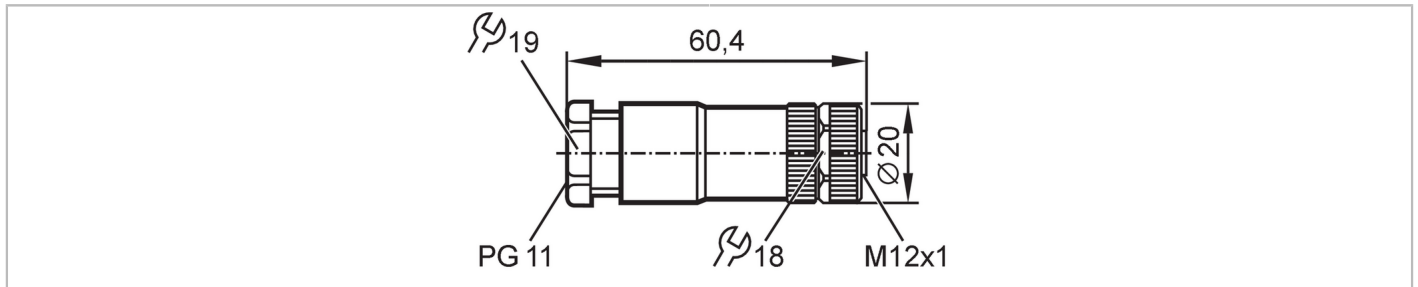

Application	
Special feature	Free from silicone; gold-plated contacts
Design	Powerkabel, T-coded
Application	Industrial applications; Oils and coolants
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 DC
Max. current load total [A]	12; (when using conductors with 1.5 mm ²)
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 67
Mechanical data	
Weight [g]	29.03
Molded-body material	PA
Material nut	diecast zinc
Sealing material	NBR
Remarks	
Pack quantity	1 pcs.

Electrical connection
 screw terminals: 0.75...1.5 mm²; Cable sheath: Ø 8...10 mm

Electrical connection - Socket
 Connector: 1 x M12, straight; coding: T; Contacts: 4, gold-plated; Moulded body: PA; Locking: diecast zinc; sealing: NBR; Tightening torque: 0.4 Nm

