


E18003



Female cordset

ADOAH040MKS0010X04

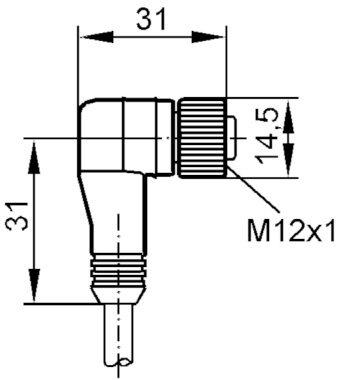

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	361.966
Dimensions	[mm]	31 x 14.5 x 31
Material		TPE
Molded-body material		TPE
Material nut		zinc, epoxy coated
Remarks		
Pack quantity		1 pcs.

E18003



Female cordset

ADOAH040MKS0010X04

Electrical connection


Cable: 10 m, TPE-S, black; 4 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated



Connection

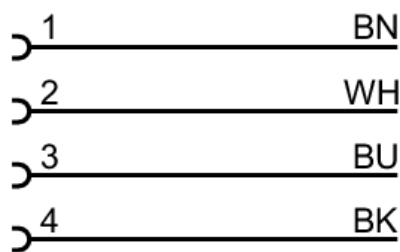

BK = Core colors :
BN = black
BU = brown
WH = blue
 white