


E18014



Female cordset

ADOGH040VAS0005E04

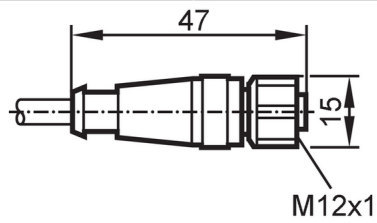

Application	
Special feature	gold-plated contacts
Application	sanitary and wet areas in the food industry
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-10...100
Protection	IP 68
Mechanical data	
Weight [g]	181.437
Dimensions [mm]	15 x 15 x 47
Molded-body material	PVC
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PVC, black, Ø 5 mm; 4 x 0.34 mm ² / AWG 22	
Electrical connection - Socket	
Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti)	


E18014



Female cordset

ADOGH040VAS0005E04

Connection

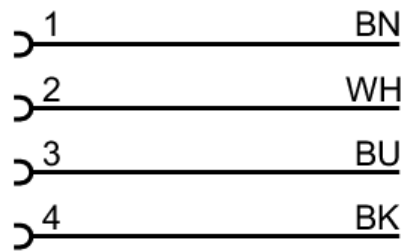

Core colors :

BK =	black
BN =	brown
BU =	blue
WH =	white