


E18014



Female cordset


ADOGH040VAS0005E04

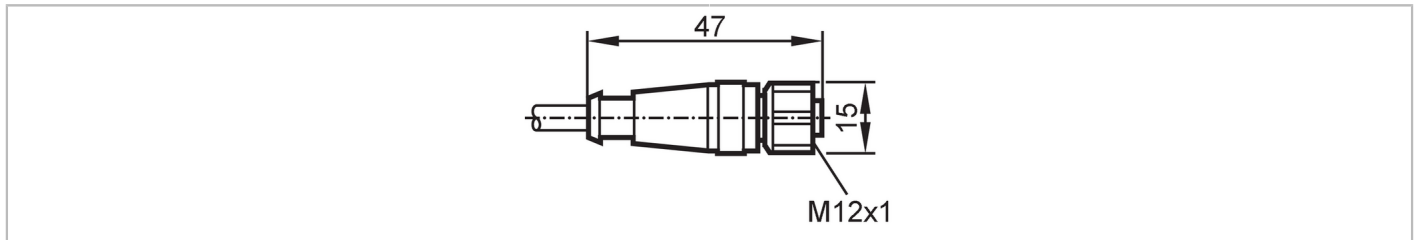

Application	
Special feature	gold-plated contacts
Application	sanitary and wet areas in the food industry
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-10...100
Protection	IP 68
Mechanical data	
Weight [g]	181.437
Dimensions [mm]	15 x 15 x 47
Molded-body material	PVC
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

Electrical connection
 Cable: 5 m, PVC, black, Ø 5 mm; 4 x 0.34 mm² / AWG 22

 Electrical connection - Socket
 Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti)



Connection	
1	BN
2	WH
3	BU
4	BK

Core colors :
 BK = black
 BN = brown
 BU = blue
 WH = white