


E18015



Female cordset

ADOGH040VAS0010E04 - BLACK

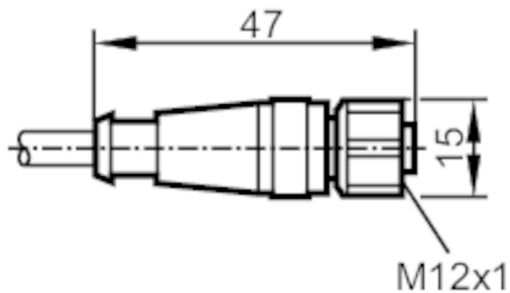

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-10...100
Protection		IP 68
Mechanical data		
Weight	[g]	362.874
Dimensions	[mm]	15 x 15 x 47
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E18015



Female cordset

ADOGH040VAS0010E04 - BLACK

Electrical connection


Cable: 10 m, PVC, black; 4 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection

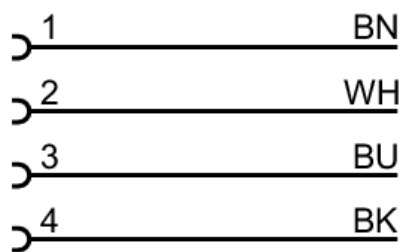

BK = Core colors :
BN = black
BU = brown
WH = blue
BK = white