


E18027



Female cordset

ADOAA050MSS0004A05

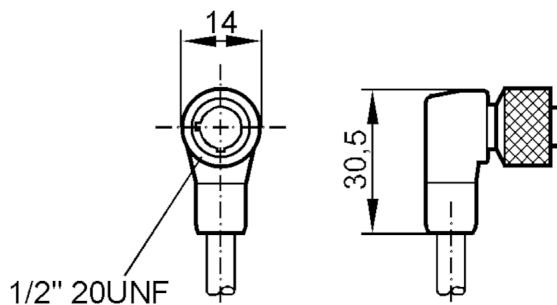

Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 250 AC/DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-40...90
Protection	IP 68
Mechanical data	
Weight [g]	181.437
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection

Cable: 4 m, PUR, black, Ø 5.3 mm; 5 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", angled; coding: C; Contacts: 5; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E18027



Female cordset

ADOAA050MSS0004A05

Connection

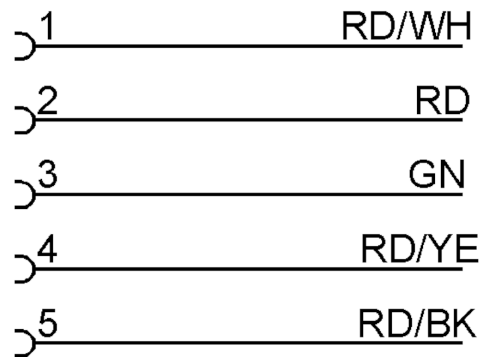

Core colors :
BK = black
GN = green
RD = red
WH = white
YE = yellow