


E18042



Female cordset

ADOGB050VAS0002E05

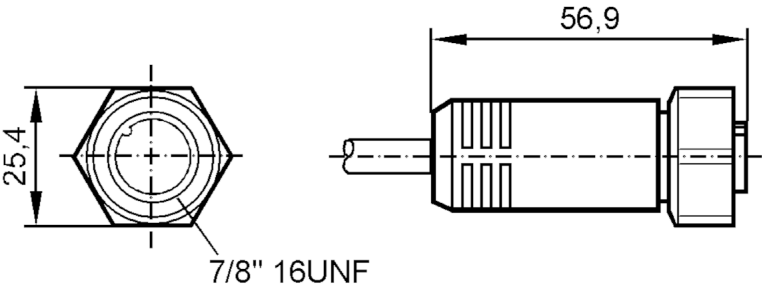

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	263.083
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E18042



Female cordset

ADOGB050VAS0002E05

Electrical connection


Cable: 2 m, PVC, grey; 5 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

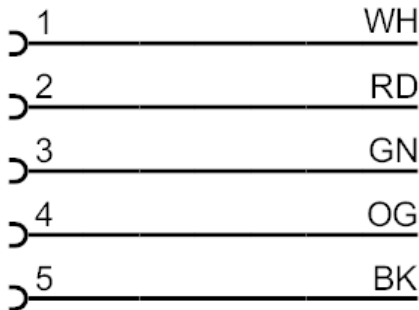

BK = Core colors :
GN = black
RD = green
OG = red
WH = orange
WH = white