


E18043



Female cordset

ADOGB050VAS0004E05

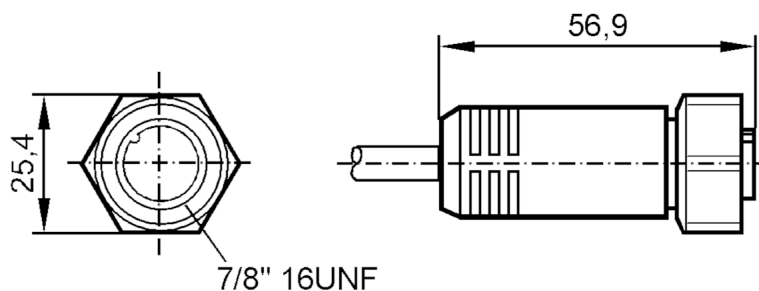

Application

System	gold-plated contacts
--------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	825.537
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E18043



Female cordset

ADOGB050VAS0004E05

Electrical connection


Cable: 4 m, PVC, grey; 5 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

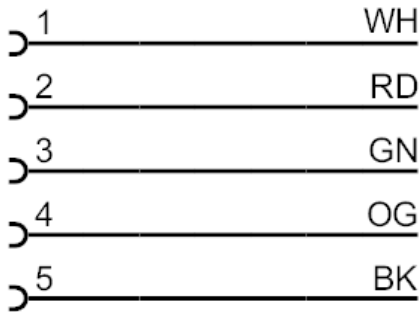

BK = Core colors :
GN = black
RD = green
OG = red
WH = orange
WH = white