


E18055



Male receptacle

RSTGB030VAS00.3-03

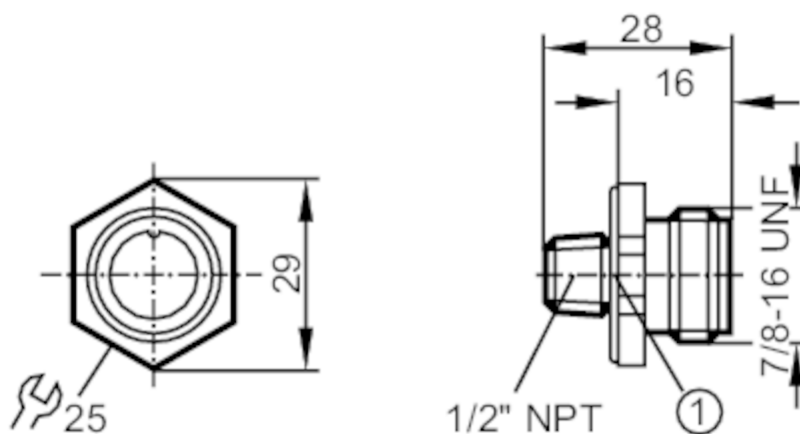

1 O-ring

Application

System gold-plated contacts

Electrical data

Operating voltage [V] < 600 AC/DC

Operating conditions

Ambient temperature [°C] -20...100

Protection IP 68

Mechanical data

Weight [g] 25.855

Mounting thread 1/2" NPT

Material stainless steel

Molded-body material stainless steel

Remarks

Pack quantity 1 pcs.

E18055



Male receptacle

RSTGB030VAS00.3-03

Electrical connection

Cable: 0.3 m, PVC; 3 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: stainless steel; Contacts: gold-plated



Connection

1	GN
2	RD
3	BK

BK = Core colors :
GN = black
RD = green
 red