


E18057



Male receptacle

RSTGH040VAS0001-04

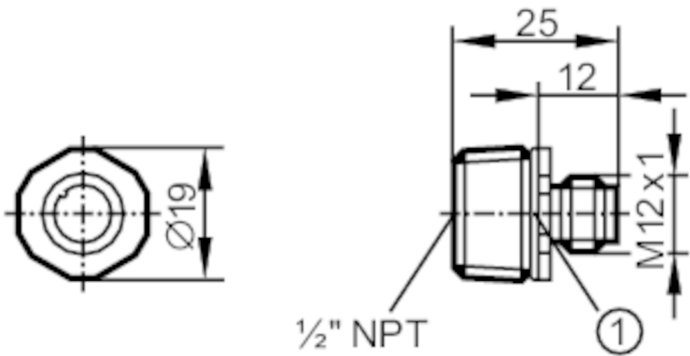

1 O-ring

Electrical data

Operating voltage [V] < 250 DC

Operating conditions

Ambient temperature [°C] -20...90

Mechanical data

Weight [g] 54.431

Mounting thread 1/2" NPT

Material stainless steel (1.4401 / 316)

Molded-body material stainless steel (1.4401 / 316)

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 1 m, PVC; 4 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: stainless steel (1.4401 / 316)



E18057



Male receptacle

RSTGH040VAS0001-04

Connection

1	BN
2	WH
3	BU
4	BK

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white