


E18058



Wirable plug

SSTGH040MSSFKPG

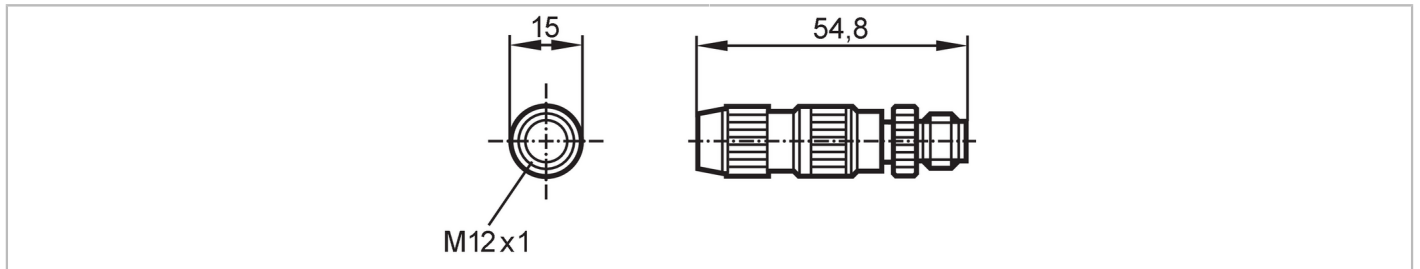

Electrical data		
Operating voltage	[V]	< 250 DC
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	22.68
Dimensions	[mm]	15 x 15 x 54.8
Molded-body material		PA 6.6
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection
insulation displacement technology: 0.14...0.34 mm²; Core insulation: PVC / PETP; (Ø 1.0...1.55 mm); Cable sheath: Ø 4...5 mm

Electrical connection - plug
Connector: 1 x M12, straight; coding: A; Contacts: 4; Moulded body: PA 6.6; Locking: brass, nickel-plated



Connection

