


E18059



Female wirable connectors

SDOGH040MSSFKPG

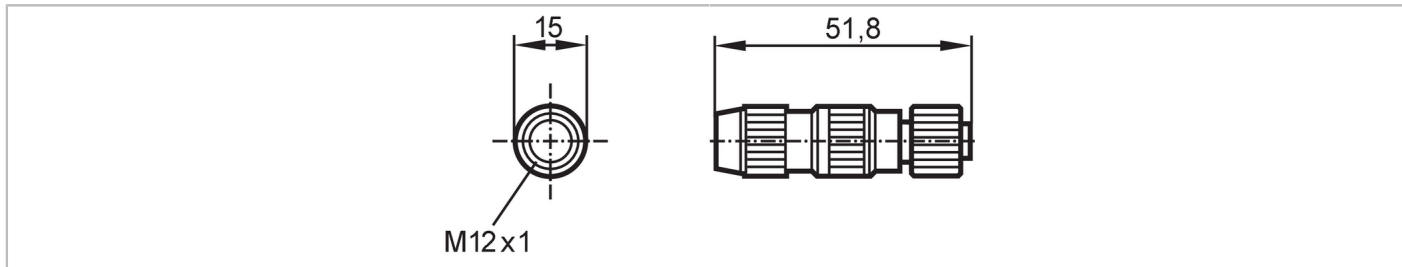

Application

Application	Industrial applications
-------------	-------------------------

Electrical data

Operating voltage	[V]	< 250 DC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	22.68
Dimensions	[mm]	15 x 15 x 51.8
Molded-body material		PA 6.6
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

insulation displacement technology: 0.14...0.34 mm²; Core insulation: PVC / PETP; (Ø 1.0...1.55 mm); Cable sheath: Ø 4...5 mm

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 4; Moulded body: PA 6.6; Locking: brass, nickel-plated



Connection

