


E18074



Male receptacle

RSTGH040ALS00.3-04

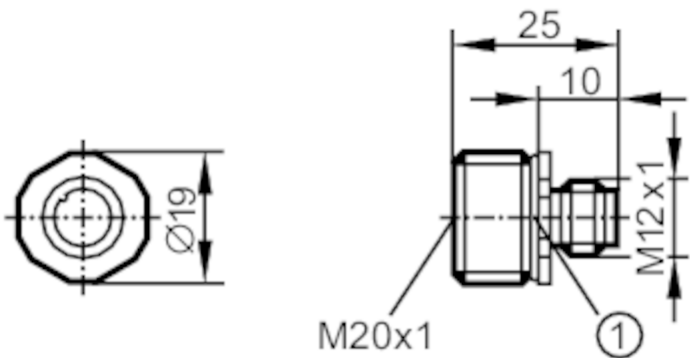

1 O-ring

Electrical data

Operating voltage	[V]	< 250 DC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-20...90
---------------------	------	----------

Mechanical data

Weight	[g]	22.68
Mounting thread		M20
Material		aluminum anodized 10...20 µm
Molded-body material		aluminum, anodized 10...20 µm

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.34 mm ² / AWG 22
--

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: aluminum, anodized 10...20 µm
--




E18074



Male receptacle

RSTGH040ALS00.3-04

Connection

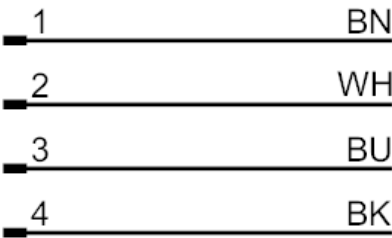

BK =	Core colors :	black
BN =		brown
BU =		blue
WH =		white