


# E18099



## Connection cable

VDOGH040VAS00.2E03STGH040VAS

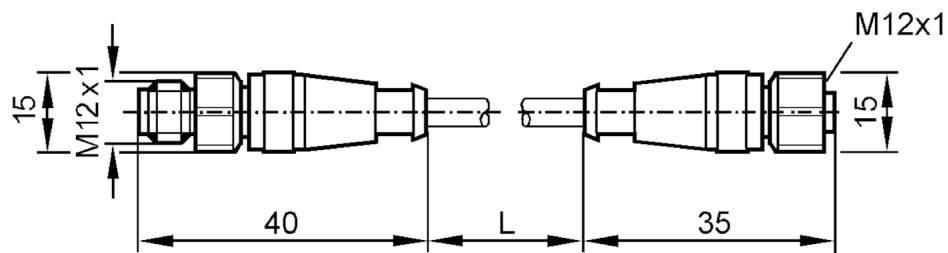

| Application          |      |                                 |
|----------------------|------|---------------------------------|
| System               |      | gold-plated contacts            |
| Electrical data      |      |                                 |
| Operating voltage    | [V]  | < 300 AC/DC                     |
| Operating conditions |      |                                 |
| Ambient temperature  | [°C] | -20...105                       |
| Protection           |      | IP 68                           |
| Mechanical data      |      |                                 |
| Weight               | [g]  | 45.359                          |
| Dimensions           | [mm] | 15 x 15 x 40                    |
| Material             |      | PVC                             |
| Molded-body material |      | PVC                             |
| Material nut         |      | stainless steel (1.4571/316Ti ) |
| Remarks              |      |                                 |
| Pack quantity        |      | 1 pcs.                          |

# E18099




## Connection cable

VDOGH040VAS00.2E03STGH040VAS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti ); Contacts: gold-plated

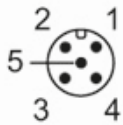

### Electrical connection

Cable: 0.2 m, PVC, grey; 3 x 0.34 mm<sup>2</sup> / AWG 22

### Connection

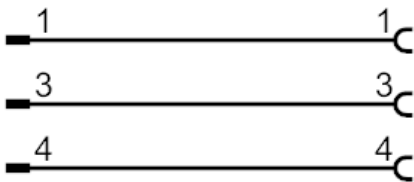

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti ); Contacts: gold-plated

