


E18112



Female cordset

ADOAH040VAS0005E04

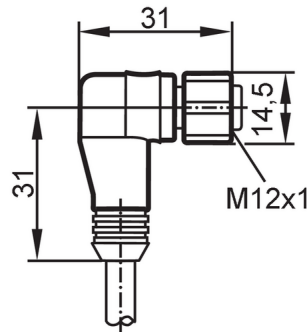

Application

Special feature	gold-plated contacts
Application	Industrial applications

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	204.116
Dimensions	[mm]	31 x 14.5 x 31
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection


Cable: 5 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Electrical connection - Socket

 Connector: 1 x M12, angled; coding: A; Contacts: 4, gold-plated; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti)



Connection

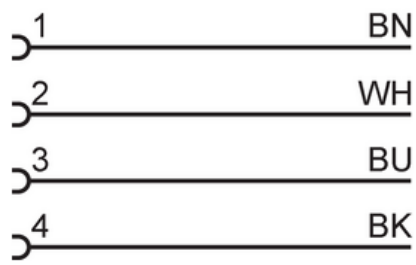

5: not used
 Core colors :
 BK = black
 BN = brown
 BU = blue
 WH = white