


E18160



Female cordset

ADOAH040VAS0075E04

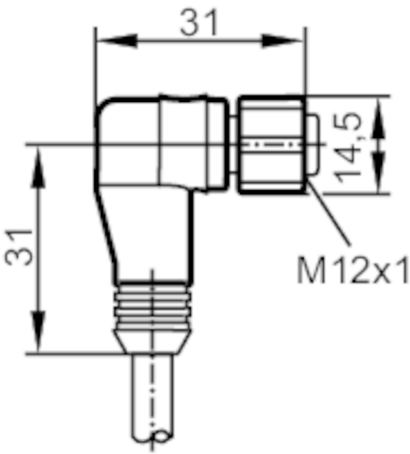

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	2685.265
Dimensions	[mm]	31 x 14.5 x 31
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E18160



Female cordset

ADOAH040VAS0075E04

Electrical connection

Cable: 75 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection



5: not used
Core colors :
BK = black
BN = brown
BU = blue
WH = white