


E18161



Female wirable connectors

SDOGH040VASFKPG9

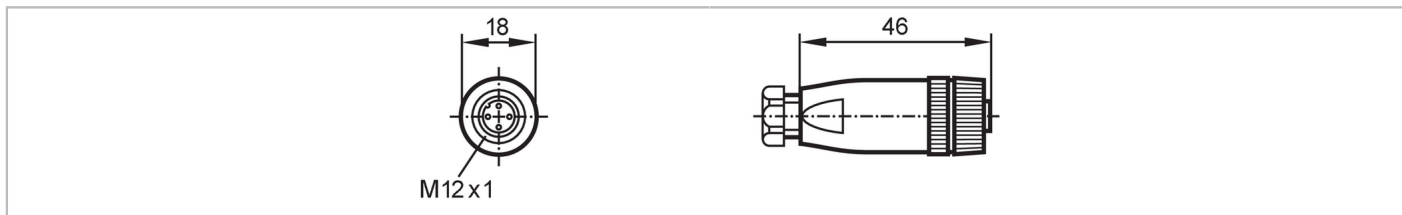

Application

Application	Industrial applications
-------------	-------------------------

Electrical data

Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-40...85
Protection	IP 68

Mechanical data

Weight [g]	27.216
Dimensions [mm]	18 x 18 x 46
Molded-body material	PA
Material nut	stainless steel (1.4571/316Ti)

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 4, pre-coppered brass; Moulded body: PA; Locking: stainless steel (1.4571/316Ti)



Connection

