


E18163



Wirable plug

SSTGH040VASFKPG7

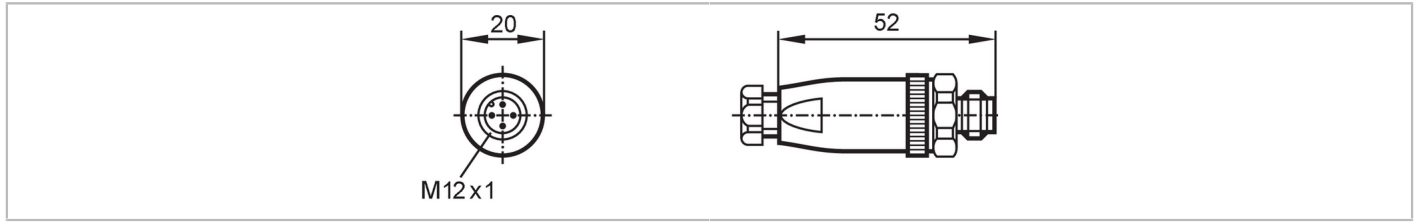

Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 68
Mechanical data	
Weight [g]	22.7
Dimensions [mm]	20 x 20 x 52
Molded-body material	PA
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

Electrical connection
 terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - plug
 Connector: 1 x M12, straight; coding: A; Contacts: 4, pre-coppered brass; Moulded body: PA; Locking: stainless steel (1.4571/316Ti)

