


# E18164



## Wirable socket

SDOGH040VASFKPG7

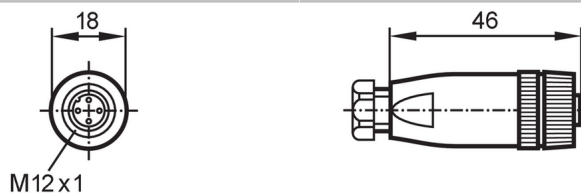

### Application

Application Industrial applications / factory automation

### Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Max. current load total [A] 4

### Operating conditions

Ambient temperature [°C] -40...85

Protection IP 68

### Mechanical data

Weight [g] 45.359

Dimensions [mm] 18 x 18 x 46

Moulded-body material PA

Material nut stainless steel (316Ti/1.4571)

### Remarks

Pack quantity 1 pcs.

### Electrical connection

terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Contacts: 4, pre-coppered brass; Moulded body: PA; Locking: stainless steel (316Ti/1.4571)



### Connection

