


# E18165



## Female wirable connectors

SDOGH080MSSFKPG

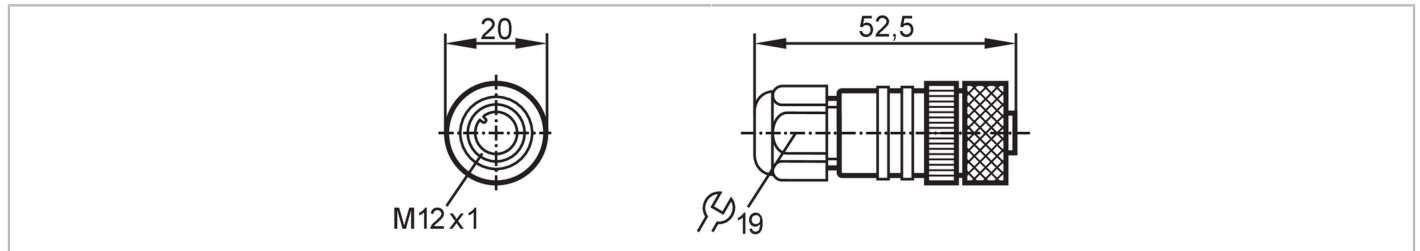

Application	
Special feature	Free from silicone; gold-plated contacts
Application	Industrial applications
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 125 AC/DC
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Ambient temperature [°C]	-25...100
Protection	IP 68
Mechanical data	
Weight [g]	45.4
Dimensions [mm]	20 x 20 x 52.5
Molded-body material	PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
terminals: ...0.75 mm <sup>2</sup> ; Cable sheath: Ø 6...8 mm	
Electrical connection - Socket	
Connector: 1 x M12, straight; coding: A; Contacts: 8, gold-plated; Moulded body: PA; Locking: brass, nickel-plated	

# E18165



## Female wirable connectors

SDOGH080MSSFKPG

### Connection

