


E18166



Female cordset

ADOGB030VAS0020E03

Article no longer available - archive entry

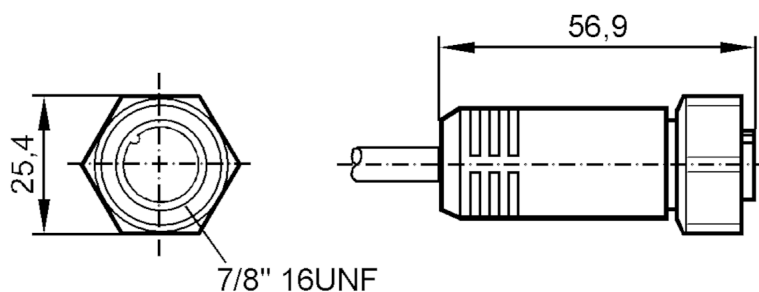

Application

System gold-plated contacts

Electrical data

Operating voltage [V] < 300 AC/DC

Operating conditions

Ambient temperature [°C] -20...105

Protection IP 68

Mechanical data

Weight [g] 5238.988

Material PVC

Molded-body material PVC

Material nut stainless steel (1.4404 / 316L)

Remarks

Pack quantity 1 pcs.

E18166



Female cordset

ADOGB030VAS0020E03

Electrical connection


Cable: 20 m, PVC, grey; 3 x 0.75 mm² / AWG 18

Electrical connection - Socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

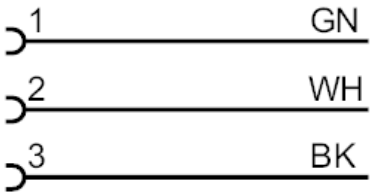

BK = Core colors :
GN = black
WH = green
 white