


E18181



Connection cable


VDOAH040VAS01.5E03STGH040VAS

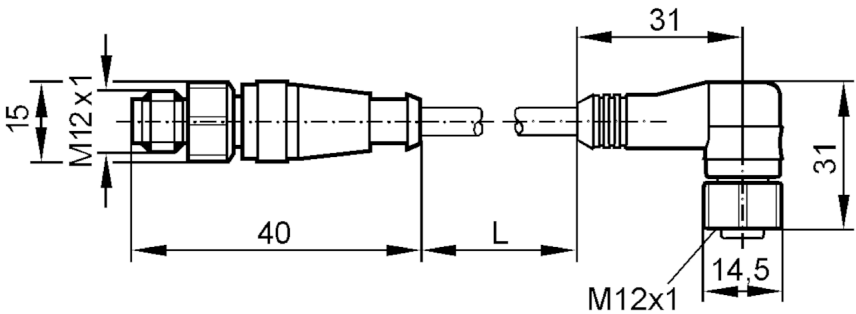

Application	
System	gold-plated contacts
Electrical data	
Operating voltage	[V] < 300 AC/DC
Operating conditions	
Ambient temperature	[°C] -20...105
Protection	IP 68
Mechanical data	
Weight	[g] 63.503
Material	TPE
Molded-body material	TPE
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

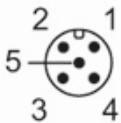

E18181




Connection cable

VDOAH040VAS01.5E03STGH040VAS

Electrical connection

Cable: 1.5 m, PVC, grey; 3 x 0.34 mm² / AWG 22

Connection

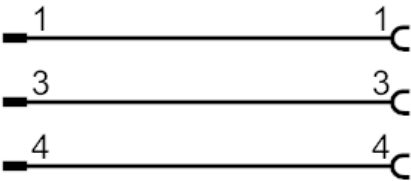

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

