




Connection cable

VDOAH040VAS02.5E03STGH040VAS

Article no longer available - archive entry

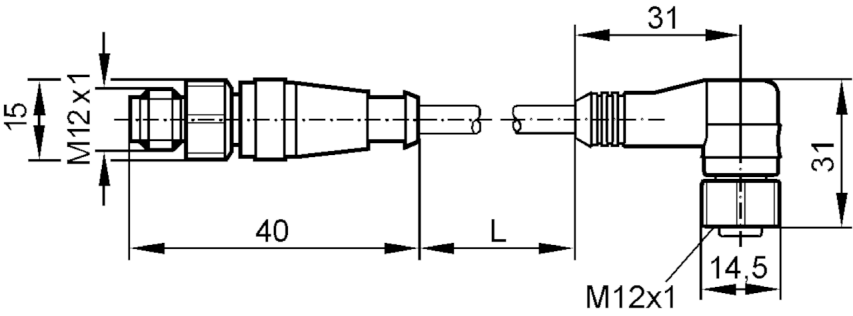

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	63.503
Material		TPE
Molded-body material		TPE
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E18182



Connection cable


VDOAH040VAS02.5E03STGH040VAS

Electrical connection

Cable: 2.5 m, PVC, grey; 3 x 0.34 mm² / AWG 22


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

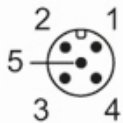

Electrical connection

Connection

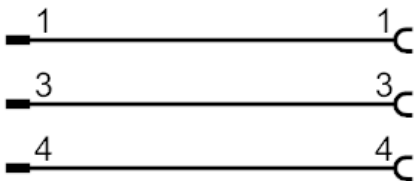

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

