


# E18202



## Female cordset

ADOGA030MSS0010X03

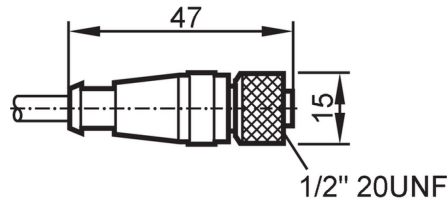

Application	
Special feature	gold-plated contacts
Application	Industrial applications
Electrical data	
Operating voltage [M]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-45...105
Protection	IP 68
Mechanical data	
Weight [g]	453.592
Dimensions [mm]	15 x 15 x 47
Molded-body material	TPE
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 10 m, TPE-S, yellow; 3 x 0.34 mm <sup>2</sup> / AWG 22	
Electrical connection - Socket	
Connector: 1 x 1/2", straight; coding: C; Contacts: 3, gold-plated; Moulded body: TPE; Locking: brass, nickel-plated	
Connection	
GN =	Core colors :
RD/BK =	green
RD/WH =	red/black
	red/white