


E18202



Female cordset

ADOGA030MSS0010X03

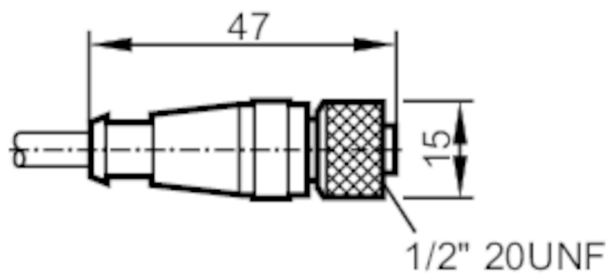

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	453.592
Dimensions	[mm]	15 x 15 x 47
Material		TPE
Molded-body material		TPE
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E18202



Female cordset

ADOGA030MSS0010X03

Electrical connection


Cable: 10 m, TPE-S, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

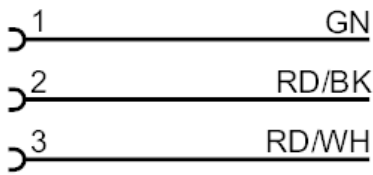

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white