


E18206



Female cordset


ADOGA030VAS0005E03

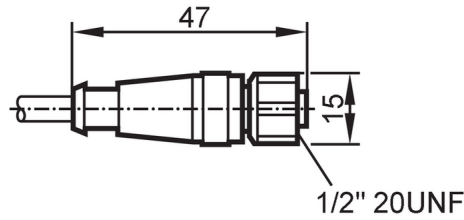

Application	
Special feature	gold-plated contacts
Application	sanitary and wet areas in the food industry
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-10...100
Protection	IP 68
Mechanical data	
Weight [g]	199.58
Dimensions [mm]	15 x 15 x 47
Molded-body material	PVC
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

Electrical connection
 Cable: 5 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

 Electrical connection - Socket
 Connector: 1 x 1/2", straight; coding: C; Contacts: 3, gold-plated; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti)



Connection	
1	GN
2	RD/BK
3	RD/WH

Core colors :
 GN = green
 RD/BK = red/black
 RD/WH = red/white